



1.

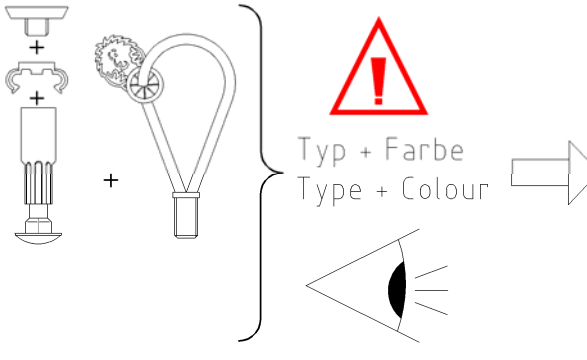

Typ + Farbe
Type + Colour


2.

Type	Farbe	Colour
Rd12 - 500kg	Orange	Orange
Rd14 - 800kg	Weiss	White
Rd16 - 1200kg	Rot	Red
Rd18 - 1600kg	Rosa	Pink
Rd20 - 2000kg	Hellgrün	Light green
Rd24 - 2500kg	Anthrazit	Anthracite
Rd30 - 4000kg	Grün	Green

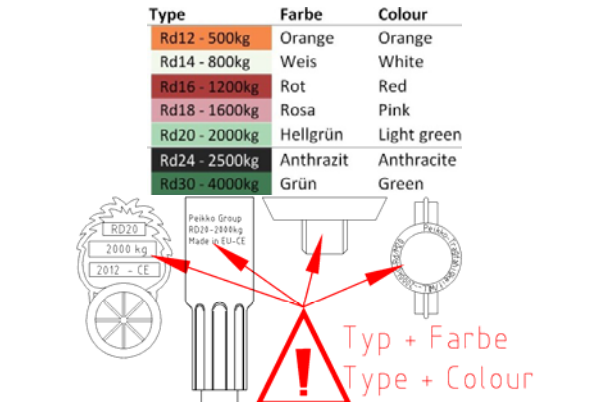


Typ + Farbe
Type + Colour


3.

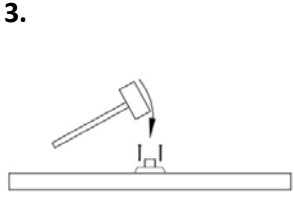


4.

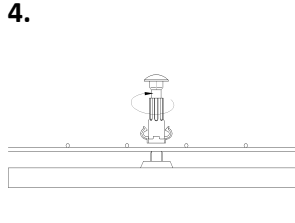


5.

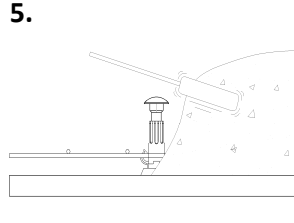


6.

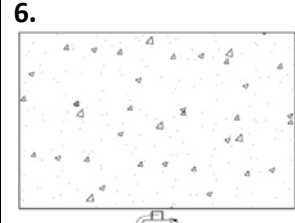

7.

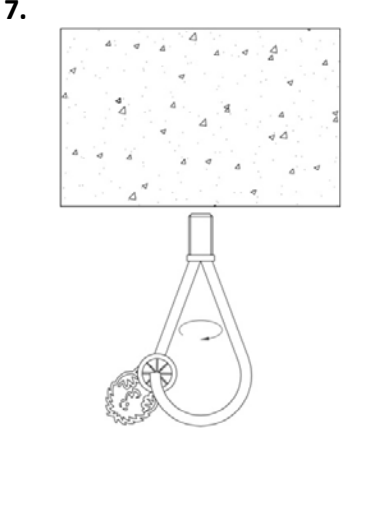


8.

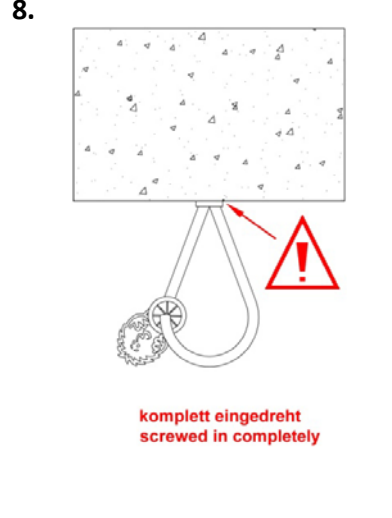


komplett eingedreht
screwed in completely

9.

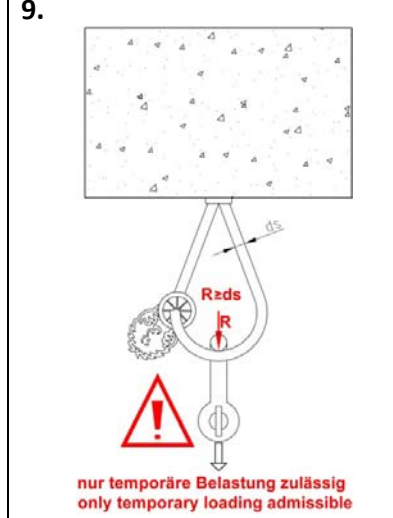

nur temporäre Belastung zulässig
only temporary loading admissible

10.

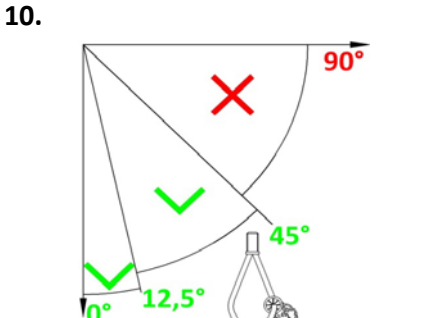

90°
0° 12,5° 45°