



The following excerpt are pages from the [North American Product Technical Guide Volume 3: Modular Support Systems Technical Guide, Edition 1](#) .

Please refer to the publication in its entirety for complete details on this product including load values, approvals/listings, general suitability, finishes, quality, etc.

To consult directly with a team member regarding our modular support system products, contact Hilti's team of technical support specialists between the hours of 7:00am – 6:00pm CST.

US: 877-749-6337 or HNATechnicalServices@hilti.com

CA: 1-800-363-4458, ext. 6 or CATechnicalServices@hilti.com

3.0 MODULAR SUPPORT SYSTEM

3.2.11 MT MEDIA FIXATION

MT-SP OC

Description


Universal low-friction slider plate with improved temperature and UV-resistance for use between pipes and MT girders or MT-U-GL1. Suitable for indoor or outdoor use with service temperatures ranging from -40° F (-40° C) to 302° F (150° C).

Material Specifications

Material
PA66-GF30 UV-stabilized

Ordering Information

Description	Weight Per Piece lbs (kg)	Quantity Piece(s)	Item No.
MT-SP OC	0.04 (0.02)	10	2368807

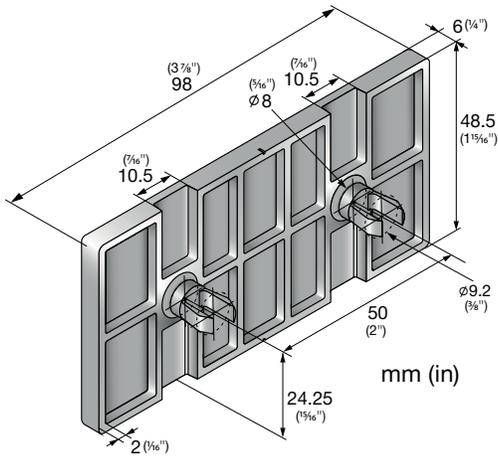

*Technical load data for MT-SP is available upon request.