


BRACKET PROFILE ADJUSTMENT

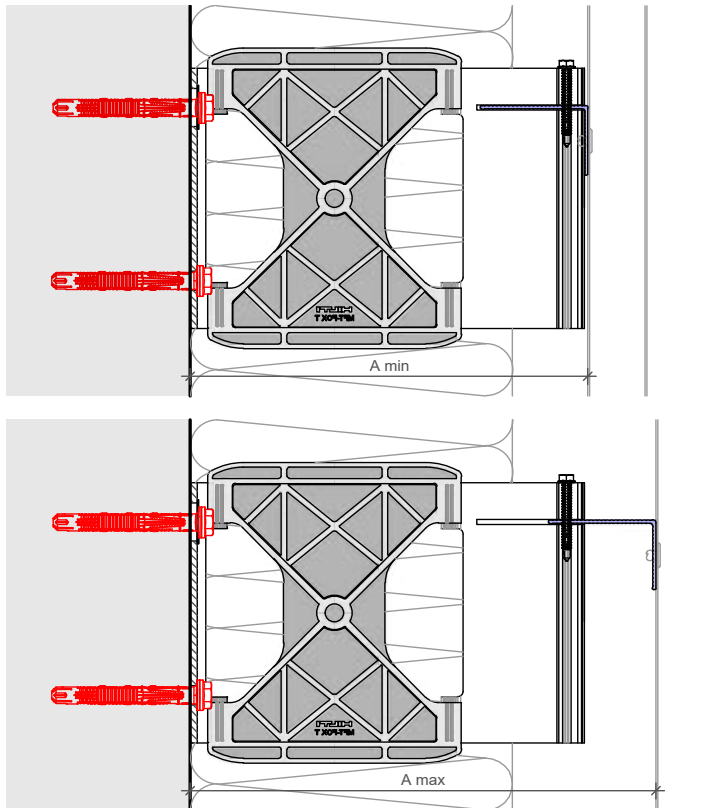

Profiles	MFT-T		MFT-T		MFT-L		MFT-L	
	1-1/2" x 3" 1-1/2" x 5"		2-1/2" x 3" 2-1/2" x 4" 2-1/2" x 5" 2-1/2" x 6"		1-1/2" x 1"		2-1/2" x 2"	
Brackets	A min* in. (mm)	A max* in. (mm)	A min* in. (mm)	A max* in. (mm)	A min* in. (mm)	A max* in. (mm)	A min* in. (mm)	A max* in. (mm)
MFT-FOX VT 140 M 6,5/11	5.5 (140)	6.2 (158.1)	5.6 (143.5)	7.2 (183.5)	5.5 (140)	6.2 (158.1)	5.6 (143.5)	7.2 (183.5)
MFT-FOX VT 160 M 6,5/11	6.3 (160)	7 (178.1)	6.4 (163.5)	8 (203.5)	6.3 (160)	7 (178.1)	6.4 (163.5)	8 (203.5)
MFT-FOX VT 180 M 6,5/11	7.1 (180)	7.8 (198.1)	7.2 (183.5)	8.8 (223.5)	7.1 (180)	7.8 (198.1)	7.2 (183.5)	8.8 (223.5)
MFT-FOX VT 200 M 6,5/11	7.9 (200)	8.6 (218.1)	8 (203.5)	9.6 (243.5)	7.9 (200)	8.6 (218.1)	8 (203.5)	9.6 (243.5)
MFT-FOX VT 220 M 6,5/11	8.7 (220)	9.4 (238.1)	8.8 (223.5)	10.4 (263.5)	8.7 (220)	9.4 (238.1)	8.8 (223.5)	10.4 (263.5)
MFT-FOX VT 240 M 6,5/11	9.4 (240)	10.2 (258.1)	9.6 (243.5)	11.2 (283.5)	9.4 (240)	10.2 (258.1)	9.6 (243.5)	11.2 (283.5)
MFT-FOX VT 260 M 6,5/11	10.2 (260)	10.9 (278.1)	10.4 (263.5)	11.9 (303.5)	10.2 (260)	10.9 (278.1)	10.4 (263.5)	11.9 (303.5)
MFT-FOX VT 280 M 6,5/11	11 (280)	12.5 (318.1)	11.2 (283.5)	12.7 (323.5)	11 (280)	11.7 (298.1)	11.2 (283.5)	12.7 (323.5)
MFT-FOX VT 300 M 6,5/11	11.8 (300)	12.5 (318.1)	11.9 (303.5)	13.5 (343.5)	11.8 (300)	12.5 (318.1)	11.9 (303.5)	13.5 (343.5)
MFT-FOX VT 320 M 6,5/11	12.6 (320)	13.3 (338.1)	12.7 (323.5)	14.3 (363.5)	12.6 (320)	13.3 (338.1)	12.7 (323.5)	14.3 (363.5)

* Distance shown does not include rail thickness.