

GO GREEN. GO FURTHER.

Green line laser PM 2-LG

The new Hilti PM 2-LG self-leveling line laser features green beam technology, which offers up to four times higher visibility compared to a standard red beam for greater working range. Select the lines you need to get the job done quickly and accurately.




*Some limitations apply. Contact Hilti for details.



Applications and advantages

- Leveling junction boxes, cable trays, radiators and pipe installations
- Leveling suspended ceiling
- Leveling and aligning doors and windows
- Transferring reference heights
- Aligning pipes and conduits
- Two green laser lines to perform a multitude of applications with maximum visibility
- Ergonomic and compact design
- Rubberized housing and pendulum lock for increased durability

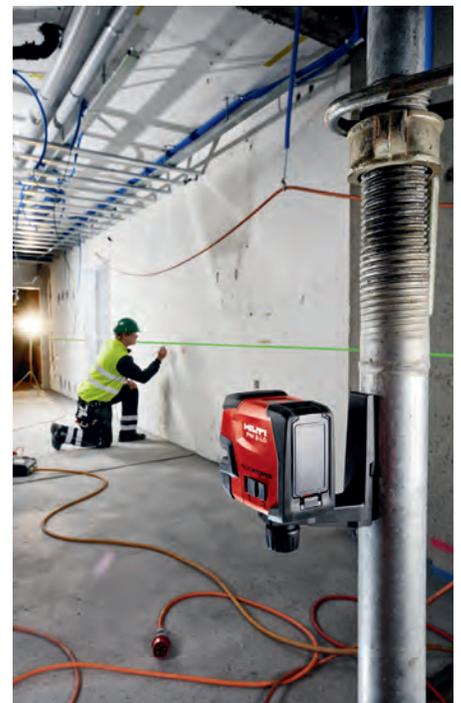

PULSE IIIPOWER

Technical Data	PM 2-LG
Accuracy	±0.12 in at 33 ft
Max. operating distance	66 ft (lines)
IP protection class	IP 54 (IEC 529)
Laser class	< 1 mW, 510-530 nm, Class 2 (IEC 60825-1:2008), Class II (FDA CFR 21 art. 1040)
Battery type	4 x 1.5 V (AA)
Operation time with alkaline battery	8 h
Operating temperature range	14 - 122 °F
Dimensions (L x W x H)	4.2 x 2.6 x 3.7 in
Weight with batteries	1.1 lb
Tripod thread diameter	1/4 in

Order Information

Description	Package Contents	Item No.
Line laser PM 2-LG	Includes tool, tool bag, batteries and operating instructions in cardboard box.	2098521
Line laser PM 2-LG with Magnetic bracket PMA 82	Includes tool, tool bag, batteries, operating instructions in cardboard box, and wall mount PMA 82 with magnetic bracket	3520501

Accessories

Wall mount PMA 82 with magnetic bracket		2098198
Magnetic bracket PMA 83		2098199
Target plate PRA 54 (green)		226976
Compact tripod PMA 20		411287

Hilti. Outperform. Outlast.

Hilti, Inc. (U.S.) | 1-800-879-8000 | en español 1-800-879-5000 | www.us.hilti.com | Hilti (Canada) Corp. | 1-800-363-4458 | www.hilti.ca

